

# Technical data sheet

## 90° Quick pipe bend, light grey

Item number: 2154054



Fitting for plastic electrical installation pipes to create 90° bends. Suitable for Quick pipe pipes or corrugated pipes. Toolless closing and opening. Can be used in a temperature range of -25 to +60 °C.



**PP** Polypropylene

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 2154054                  |
| Type                               | 3000 BMS M20 LGR         |
| Description 1                      | 90° Quick pipe bend      |
| Manufacturer                       | OBO                      |
| Dimension                          | M20                      |
| Colour                             | Light grey; RAL 7035     |
| Material                           | Polypropylene            |
| Smallest sales unit                | 5                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 1.103 kg                 |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0829 kg CO2e / 1 Piece |


# Technical data sheet

## 90° Quick pipe bend, light grey

Item number: 2154054



### Dimensions

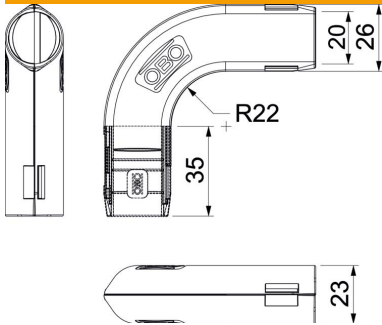

|              |         |
|--------------|---------|
| Dimension B  | 26.3 mm |
| Dimension d  | 20 mm   |
| Dimension L  | 83.2 mm |
| Dimension L1 | 35 mm   |
| Dimension R  | 22 mm   |

### Technical data

|                                   |           |
|-----------------------------------|-----------|
| Version for                       | Connector |
| Flexible                          | no        |
| Halogen-free                      | yes       |
| With inspection opening and lid   | no        |
| With sleeve                       | no        |
| Brushed surface                   | no        |
| Polished surface                  | no        |
| ROHS-conformant                   | yes       |
| Permitted temperature range, max. | 60 °C     |
| Permitted temperature range, min. | 0 °C      |
| Angle of the bend                 | 90 °      |
| Two-part                          | yes       |