

Technical data sheet

Collecting clamp Grip 20, plastic

Item number: 2205404



Collection clamp with pointed fastening element, for the mounting of up to 20 cables NYM 3 x 1.5 mm² **on walls or ceilings**. Fastening with impact anchor or push-fit anchor. Also suitable for the fastening with gas- and battery-operated setting tools of the brands Bosch, Fischer and Spit (inner nose diameter Ø 7 mm). Fastening hole: Ø 6 mm. Recommended fastening distance of 250–400 cm when fully assigned, depending on the respective applicable national specifications/norms. With multifunctional fastening element.

Capacity: 2031/ 20 max. 20 cables NYM 3 x 1.5 mm²



PP Polypropylene

Master data

Item number	2205404
Type	2031 20
Description 1	Grip collecting clamp
Manufacturer	OBO
Dimension	20x NYM3x1,5
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.92 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0779 kg CO2e / 1 Piece


Technical data sheet

Collecting clamp Grip 20, plastic

Item number: 2205404



Dimensions

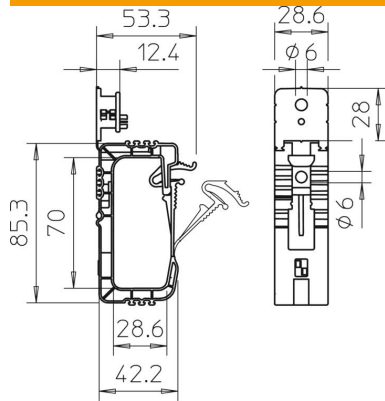

Technical data

No. of conductors NYM 3 x 1.5	20
Flame-resistant version	no
Breaking load	0.32 kN
Maintain electrical functions	no
Halogen-free	yes
With anchor	no
ROHS-conformant	yes