

Technical data sheet

Collecting clamp Grip M UNI, metal FS, for direct fastening

Item number: 2207214



Metal collection clamp for laying cables on walls or ceilings. Direct fastening via a plastic adapter or via classic screw mounting through a separate fastening hole $\varnothing 6 \text{ mm}$. Universal adapter for single-handed mounting with various firing tools, such as from Hilti, Würth, Spit, Bosch. High mechanical resistance also in the event of fire. Halogen-free, non-combustible. Suitable for safe mounting above fire protection ceilings. Also approved as a cable-specific variant for the maintenance of electrical functionality to DIN 4102 part 12. The lock can be opened without tools. Detailed information on the approved routing variants can be found in the appropriate testing documentation.



St	Steel
FS	Strip galvanised

Master data

Item number	2207214
Type	2031 M UNI 20 FS
Description 1	Grip collecting clamp
Description 2	for direct fastening
Manufacturer	OBO
Dimension	20x NYM3x1,5
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	50
Unit of quantity	Piece
Weight	4.74 kg
Weight unit	kg/100 pc.


Technical data sheet

Collecting clamp Grip M UNI, metal FS, for direct fastening

Item number: 2207214



Dimensions

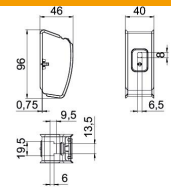

Technical data

No. of conductors NYM 3 x 1.5	20
Maintain electrical functions	yes
Halogen-free	yes
With anchor	no
ROHS-conformant	yes