

Technical data sheet

ISO nail clip, type 4029 4-7

Item number: 2215071



OBO makes various fastening systems available for fastening cables securely on different substrates. Starting with the adhesive clip or ISO nail clips for fastening, e.g. on wooden beams, up to the Nail-Fix for fixing in masonry slits, OBO can offer a wide range of clips for nail fastening, suitable for steel nails 2 mm.




PP Polypropylene

Master data

Item number	2215071
Type	4029
Description 1	ISO nail clip
Manufacturer	OBO
Dimension	4-7mm
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.028 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0012 kg CO2e / 1 Piece

Dimensions

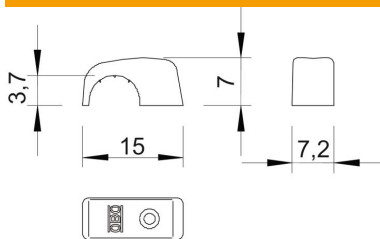

Dimension B	7.2 mm
Dimension H	7 mm
Dimension H1	3.7 mm
Dimension L	15 mm

Technical data sheet

ISO nail clip, type 4029 4-7

Item number: 2215071



Technical data

Double clip	no
Shape	Round (for round conductor)
for cable diameter, max.	7 mm
for cable diameter, min.	4 mm
For nail diameter	2,0
Hardened	no
Halogen-free	yes
With nail	no
ROHS-conformant	yes
Impact-resistant	no