

Technical data sheet

Impact clip, light grey

Item number: 2251256



Series clip without metallic parts, thus protected against corrosion;
Use: Lock the clip in the profile rail and fix it by hitting it with a hammer.

Also suitable for rails with 11–12 mm slot width.



PS Polystyrene

Master data

Item number	2251256
Type	2047 5-25 LGR
Description 1	Impact clip
Manufacturer	OBO
Dimension	5-25mm
Colour	Light grey
Material	Polystyrene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.32 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,012 kg CO2e / 1 Piece


Technical data sheet

Impact clip, light grey

Item number: 2251256



Dimensions

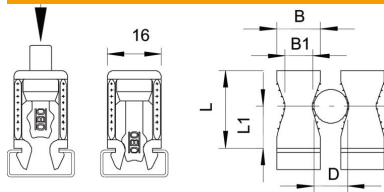

Dimension A	16 mm
Dimension B	13 mm
Dimension B1	8 mm
Dimension H	23 mm
Dimension H1	12.5 mm

Technical data

Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Rail fastening
for rail with slot width (with interval), max.	12 mm
for rail with slot width (with interval), min.	11 mm
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
ROHS-conformant	yes
Impact-resistant	yes
Clamping range D, max.	25 mm
Clamping range D, min.	5 mm
UV-resistant	no