

Technical data sheet

Series clip, light grey

Item number: 2254034



Also suitable for rails of 11 ÷ 12 mm slot width; polystyrene clip element, impact resistant, halogen-free, light grey RAL 7035; metal parts: electrogalvanised steel.



PS Polystyrene

Master data

Item number	2254034
Type	2051 8-36 LGR
Description 1	Series clip
Description 2	with cross-head screw
Manufacturer	OBO
Dimension	8-36mm
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.851 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0288 kg CO2e / 1 Piece


Technical data sheet

Series clip, light grey

Item number: 2254034



Dimensions

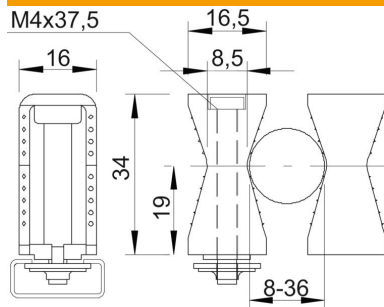

Dimension B	17 mm
Dimension B1	7.5 mm
Dimension H	34 mm
Dimension H1	18 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Fastening type	Rail fastening
for rail with slot width (with interval), max.	12 mm
for rail with slot width (with interval), min.	11 mm
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Nominal diameter	36 mm
Impact-resistant	no
Bolt	M4 x 40
Clamping range D, max.	36 mm
Clamping range D, min.	8 mm
UV-resistant	no