

Technical data sheet

Series clip, light grey

Item number: 2255014



Heavyweight version, also suitable for rails of 16 ÷ 17 mm slot width; polyamide clip element, light grey RAL 7035; Metal parts: Electrogalvanised steel.



PA Polyamide

Master data

Item number	2255014
Type	2054 14-48 LGR
Description 1	Series clip
Description 2	with cross-head screw
Manufacturer	OBO
Dimension	14-48mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	25
Unit of quantity	Piece
Weight	4.32 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1722 kg CO2e / 1 Piece


Technical data sheet

Series clip, light grey

Item number: 2255014



Dimensions

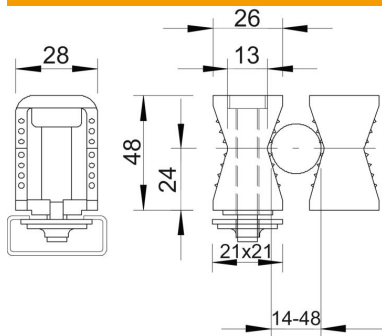

Dimension B	26 mm
Dimension B1	14.5 mm
Dimension H	48 mm
Dimension H1	24 mm

Technical data

Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Rail fastening
for rail with slot width (with interval), max.	17 mm
for rail with slot width (with interval), min.	16 mm
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
ROHS-conformant	yes
Impact-resistant	no
Bolt	M8 x 60
Clamping range D, max.	48 mm
Clamping range D, min.	14 mm
UV-resistant	no