

Technical data sheet

Cable tie, white

Item number: 2331860



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.



PA Polyamide

Master data		
Item number	2331860	
Type	565 4.8x120 WS	
Description 1	Cable ties	
Manufacturer	OBO	
Dimension	4,8x120mm	
Colour	White	
Material	Polyamide	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	0.089 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0036 kg CO2e / 1 Piece	


Technical data sheet

Cable tie, white

Item number: 2331860



Dimensions

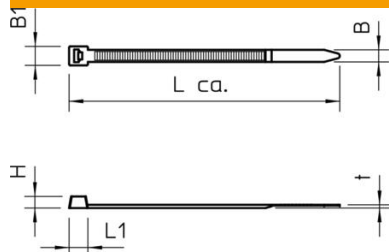

Length	120 mm
Width	4.8 mm
Height	1.5 mm
Dimension B	4.8 mm
Dimension L	120 mm
Dimension t	1.5 mm

Technical data

Version for	Externally toothed
Strip closure	Plastic tongue/tab
Fastening type	Without
Labelling area	Without
Halogen-free	yes
Releasable lock	no
Max. Bundle diameter	27 mm
MIL approval	no
Mounting temperature, max.	90 °C
Min. mounting temperature	-30 °C
Reflective	no
ROHS-conformant	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-30 °C
Transparent	no
UL approval	yes
UV-resistant	no
VG approval	no
Tensile strength	220 N