

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331862



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.




PA Polyamide

Master data

Item number	2331862
Type	565 4.8x120 SWUV
Description 1	Cable ties
Description 2	UV-resistant
Manufacturer	OBO
Dimension	4.8x120mm
Colour	Black
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.089 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0036 kg CO2e / 1 Piece

Dimensions

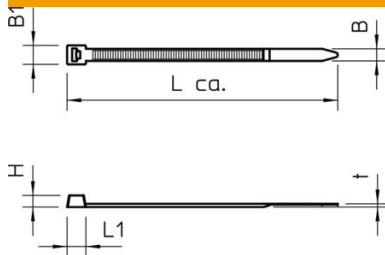

Length	120 mm
Width	4.8 mm
Height	1.5 mm
Dimension B	4.8 mm
Dimension L	120 mm
Dimension t	1.5 mm

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331862



Technical data

Version for	Externally toothed
Strip closure	Plastic tongue/tab
Fastening type	Without
Labelling area	Without
Halogen-free	yes
Releasable lock	no
Max. Bundle diameter	27 mm
MIL approval	no
Mounting temperature, max.	90 °C
Min. mounting temperature	-30 °C
Reflective	no
ROHS-conformant	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-30 °C
Transparent	no
UL approval	yes
UV-resistant	yes
VG approval	no
Tensile strength	220 N