

Technical data sheet

Cable tie, white

Item number: 2331866



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.



PA

Polyamide

Master data

Item number	2331866
Type	565 4.8x160 WS
Description 1	Cable ties
Manufacturer	OBO
Dimension	4,8x160mm
Colour	White
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.12 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0047 kg CO2e / 1 Piece


Technical data sheet

Cable tie, white

Item number: 2331866



Dimensions

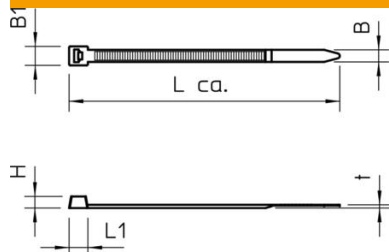

Length	160 mm
Width	4.8 mm
Height	1.6 mm
Dimension B	4.8 mm
Dimension L	160 mm
Dimension t	1.6 mm

Technical data

Version for	Externally toothed
Strip closure	Plastic tongue/tab
Fastening type	Without
Labelling area	Without
Halogen-free	yes
Releasable lock	no
Max. Bundle diameter	39 mm
MIL approval	no
Mounting temperature, max.	90 °C
Min. mounting temperature	-30 °C
Reflective	no
ROHS-conformant	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-30 °C
Transparent	no
UL approval	yes
UV-resistant	no
VG approval	no
Tensile strength	220 N