

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331874



Cable ties are used for quick, uncomplicated fixing or bundling of cables and pipes to cable support systems or other mounting structures.




PA

Polyamide

Master data

Item number	2331874
Type	565 4.8x200 SWUV
Description 1	Cable ties
Description 2	UV-resistant
Manufacturer	OBO
Dimension	4.8x200mm
Colour	Black
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.149 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,006 kg CO2e / 1 Piece

Dimensions

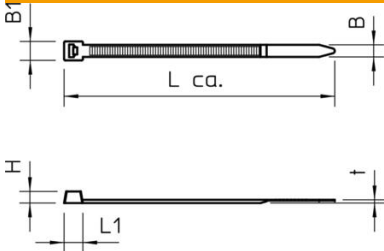

Length	200 mm
Width	4.8 mm
Height	1.6 mm
Dimension B	4.8 mm
Dimension L	200 mm
Dimension t	1.6 mm

Technical data sheet

Cable tie, black, UV and weather-resistant

Item number: 2331874



Technical data

Version for	Externally toothed
Strip closure	Plastic tongue/tab
Fastening type	Without
Labelling area	Without
Halogen-free	yes
Releasable lock	no
Max. Bundle diameter	52 mm
MIL approval	no
Mounting temperature, max.	90 °C
Min. mounting temperature	-30 °C
Reflective	no
ROHS-conformant	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-30 °C
Transparent	no
UL approval	yes
UV-resistant	yes
VG approval	no
Tensile strength	220 N