

Technical data sheet

CTC cable tie clip

Item number: 2332790



Cable tie clip for easy and quick mounting of various cables, cable bundles and pipe dimensions.

- * Universally applicable for cables and pipes
- * Fastening using knock-in anchors Ø 5 mm and Ø 6 mm
- * Max. bundle up to 63 mm
- * Halogen-free
- * UL-certified.



PA Polyamide

Master data

Item number	2332790
Type	CTC 7,5x180 LGR
Description 1	Cable tie clip
Manufacturer	OBO
Dimension	7,5x180mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.6 kg
Weight unit	kg/100 pc.


Technical data sheet

CTC cable tie clip

Item number: 2332790



Dimensions

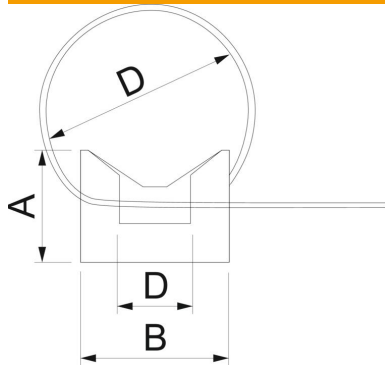

Length	180 mm
Width	7.5 mm
Height	1.5 mm
Dimension B	7.5 mm

Technical data

Strip closure	Plastic tongue/tab
Labelling area	Without
Halogen-free	yes
Max. Bundle diameter	32 mm
minimum breaking load	0.36 kN
Mounting temperature, max.	35 °C
Min. mounting temperature	-15 °C
Reflective	no
Permitted temperature range, max.	85 °C
Permitted temperature range, min.	-40 °C
Transparent	no
Tensile strength	360 N