

Technical data sheet

Gas concrete anchor 6

Item number: 2347229



The anchor can be knocked directly into the porous concrete (gas concrete resistance class AAC2 or AAC3). With a resistance class of AAC4 or greater, a 3,5 mm hole should be pre-drilled.
Screw length: Component thickness + 40 mm (6 mm) / 55 mm (8 mm).



PA Polyamide

Master data

Item number	2347229
Type	910 GD 6x35
Description 1	Gas concrete anchor
Manufacturer	OBO
Dimension	6x35mm
Colour	Light grey
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.094 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0048 kg CO2e / 1 Piece


Technical data sheet

Gas concrete anchor 6


Item number: 2347229



Dimensions

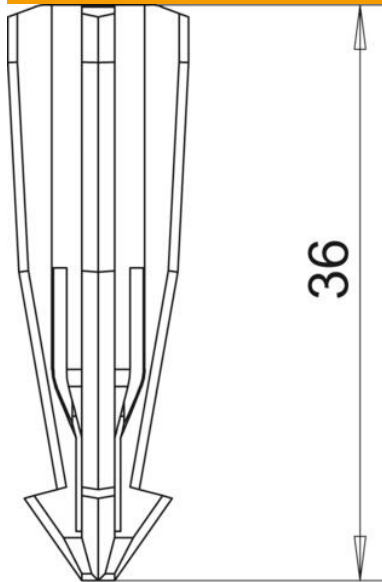

Length	35 mm
Dimension D	6 mm
Dimension L	35 mm

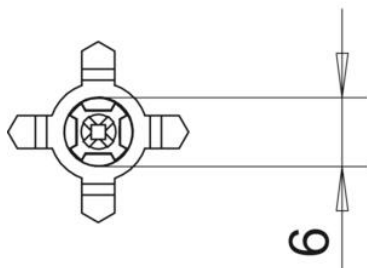

Technical data

Drill hole depth	41 mm
Suitable for fastening with cable ties	no
Suitable for gas concrete	yes
Suitable for screw diameter, max.	5 mm
Suitable for screw diameter, min.	3.5 mm
Suitable for hexagonal wood screw	yes
Halogen-free	yes
With edge	no
With bolts	no
Porous concrete P2 Fempf.	100
Porous concrete P4 Fempf.	400
ROHS-conformant	yes