

Technical data sheet

Universal anchor

Item number: 2347752



Universal nylon anchor for mounting light components on walls and ceilings. Suitable for concrete, calcareous limestone, full brick, hollow brick and porous concrete. The given load values are valid for wood screws with the specified diameter.




PA Polyamide

Master data

Item number	2347752
Type	UX 12x70
Description 1	Universal anchor
Manufacturer	OBO
Dimension	12x70
Colour	Light grey
Material	Polyamide
Smallest sales unit	25
Unit of quantity	Piece
Weight	0.435 kg
Weight unit	kg/100 pc.

Dimensions

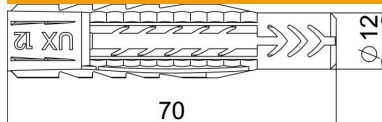

Length	70 mm
Dimension D	12 mm
Dimension L	70 mm

Technical data sheet

Universal anchor

Item number: 2347752



Technical data

Version for	Universal anchor
Concrete Frat	1500
Drill hole depth	85 mm
Drill hole diameter, max.	12 mm
Drill hole diameter, min.	12 mm
Suitable for fastening with cable ties	no
Suitable for gas concrete	yes
Suitable for screw diameter, max.	10 mm
Suitable for screw diameter, min.	8 mm
Suitable for hexagonal wood screw	yes
Porous calcareous sandstone KSL12 Fempf.	800
With edge	no
With bolts	no
Porous concrete P4 Fempf.	600
ROHS-conformant	yes
Full brick Mz12 Frat	700
Suitable for material	Calcareous sandstone Porous concrete Concrete Chipboard plate Gas concrete Natural stone Plasterboard Full brick Hollow brick
Mounting type, anchor, tie	Push-through mounting