

Technical data sheet

OBO anchor G

Item number: 3100154



Hardened steel, electrogalvanised with M6 x 8 mm thread.



St	Steel
G	Electrogalvanised

Master data

Item number	3100154
Type	903 15 G
Description 1	OBO plug
Description 2	knock-in anchor
Manufacturer	OBO
Dimension	M6, L15mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.33 kg
Weight unit	kg/100 pc.


Technical data sheet

OBO anchor G

Item number: 3100154



Dimensions

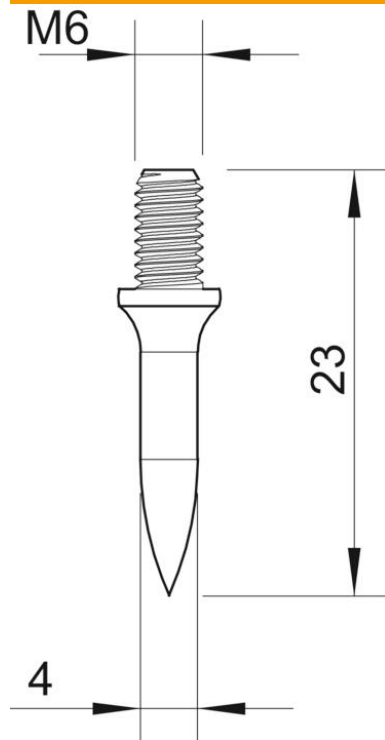

Length	23 mm
Dimension d min.	4 mm
Dimension G	M6 mm
Dimension L	23 mm

Technical data

Hardened	yes
Thread metric	6
Thread type	Metric
Thread length	8 mm
ROHS-conformant	yes
Shank length	15
Impact-resistant	no