

Technical data sheet

Hexagonal bolt M10 F

Item number: 3160755



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.



St

Steel

F

Hot galvanised

Master data

Item number	3160755
Type	SKS 10x25 F
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M10x25
Colour	zinc
Material	Steel
Surface	Hot galvanised
Surface standard	DIN 267, Teil 10
Smallest sales unit	20
Unit of quantity	Piece
Weight	4.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1057 kg CO2e / 1 Piece

Technical data sheet


Hexagonal bolt M10 F

Item number: 3160755



Dimensions

Length	25 mm
Dimension d	10 mm
Dimension L	25 mm

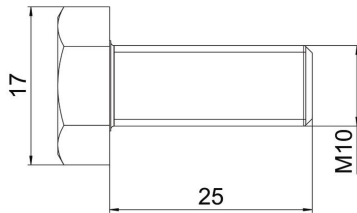

Technical data

Resistance grade	8.8
Thread	M 10 x 25
Thread metric	10
Thread type	Metric
Thread length	25 mm
Thread increase	1.5 mm
Head shape	Hexagonal
With nut	yes
With washer	yes
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no