

# Technical data sheet

## Hexagonal nut DIN 934 V2A

Item number: 3397068



Hexagonal nut to DIN 934 with metric thread.



**A2** Stainless steel

**2B** Bright, treated

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 3397068                  |
| Type                               | HN M6 A2                 |
| Description 1                      | Hexagonal nut            |
| Manufacturer                       | OBO                      |
| Dimension                          | M6                       |
| Material                           | Stainless steel          |
| Surface                            | Bright, treated          |
| Surface standard                   |                          |
| Smallest sales unit                | 100                      |
| Unit of quantity                   | Piece                    |
| Weight                             | 0.215 kg                 |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0106 kg CO2e / 1 Piece |


# Technical data sheet

## Hexagonal nut DIN 934 V2A

Item number: 3397068



### Dimensions

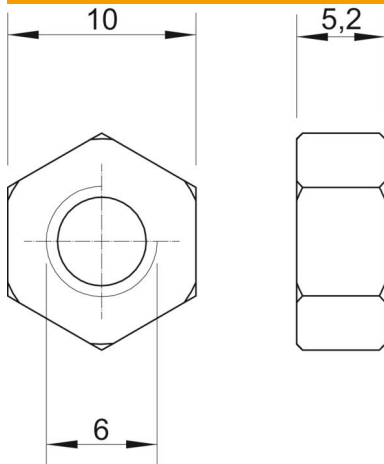

|             |        |
|-------------|--------|
| Dimension d | 6 mm   |
| Dimension h | 5.2 mm |

### Technical data

|                  |              |
|------------------|--------------|
| Thread           | M6           |
| Thread metric    | 6            |
| Thread type      | Metric       |
| Halogen-free     | yes          |
| With flange      | no           |
| ROHS-conformant  | yes          |
| WAF              | 10           |
| Self-locking     | no           |
| Left thread      | no           |
| Thread, imperial | 1/4"         |
| Nut version      | Nut          |
| Screw system nut | Hexagon head |