

Technical data sheet

Hexagonal nut DIN 934 V4A

Item number: 3397145



Hexagonal nut to DIN 934 with metric thread.



A4 Stainless steel

2B Bright, treated

Master data

Item number	3397145
Type	HN M12 A4
Description 1	Hexagonal nut
Manufacturer	OBO
Dimension	M12
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.73 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0834 kg CO2e / 1 Piece


Technical data sheet

Hexagonal nut DIN 934 V4A

Item number: 3397145



Dimensions

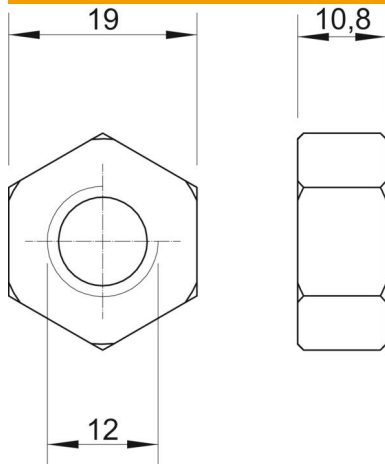

Dimension d	12 mm
Dimension h	10.8 mm

Technical data

Resistance grade	8
Thread	M12
Thread metric	12
Thread type	Metric
Halogen-free	yes
With flange	no
ROHS-conformant	yes
WAF	19
Self-locking	no
Left thread	no
Thread, imperial	1/2"
Nut version	Nut
Screw system nut	Hexagon head