


Technical data sheet

Hexagonal nut DIN 934 G

Item number: 3400042



Hexagonal nut to DIN 934 with metric thread.

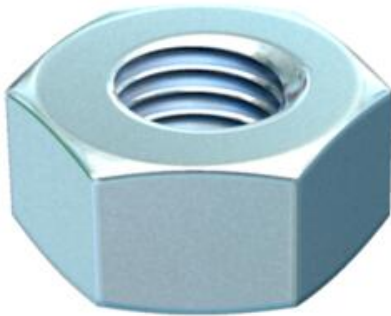

St	Steel
G	Electrogalvanised

Master data

Item number	3400042
Type	HN M4 G
Description 1	Hexagonal nut
Manufacturer	OBO
Dimension	M4
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.081 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0022 kg CO2e / 1 Piece


Technical data sheet

Hexagonal nut DIN 934 G

Item number: 3400042



Dimensions

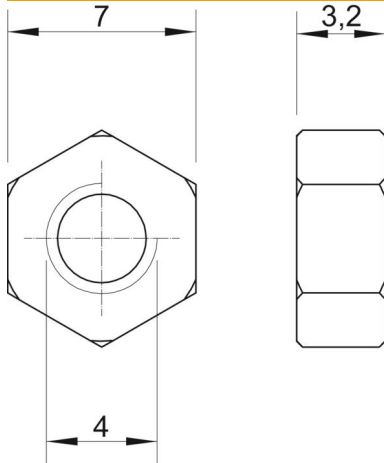

Dimension d	4 mm
Dimension h	3.2 mm

Technical data

Resistance grade	8.8
Thread	M4
Thread metric	4
Thread type	Metric
Halogen-free	yes
With flange	no
ROHS-conformant	yes
WAF	7
Self-locking	no
Left thread	no
Nut version	Nut
Screw system nut	Hexagon head