


Technical data sheet

Hexagonal nut DIN 934 G

Item number: 3400123



Hexagonal nut to DIN 934 with metric thread.

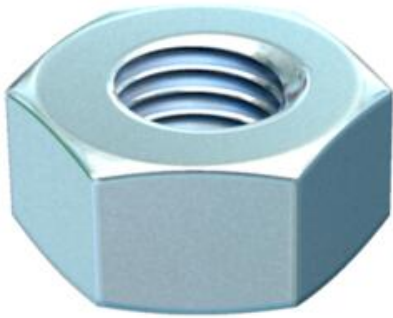

St	Steel
G	Electrogalvanised

Master data

Item number	3400123
Type	HN M12 G
Description 1	Hexagonal nut
Manufacturer	OBO
Dimension	M12
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.73 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0369 kg CO2e / 1 Piece


Technical data sheet

Hexagonal nut DIN 934 G

Item number: 3400123



Dimensions

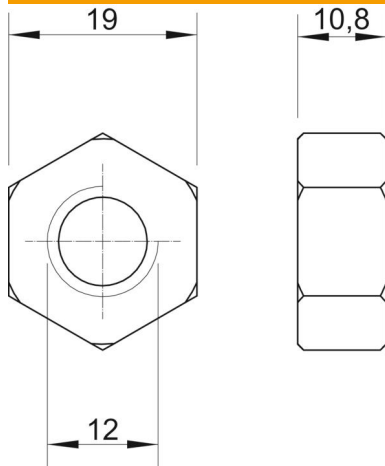

Dimension d	12 mm
Dimension h	10.8 mm

Technical data

Resistance grade	8.8
Thread	M12
Thread metric	12
Thread type	Metric
Halogen-free	yes
With flange	no
WAF	19
Self-locking	no
Left thread	no
Thread, imperial	1/2"
Nut version	Nut
Screw system nut	Hexagon head