

Technical data sheet

Plasterboard anchor

Item number: 3483214



To fasten components to plasterboard or fibre composite plates.

Minimum plate thickness: 12 mm.

For Ø 4.5 Golden Sprint or Sprint screws.




Zn

Die-cast zinc

Master data

Item number	3483214
Type	910 GKDM 12x30
Description 1	Plasterboard anchor
Description 2	for 12 mm plasterboard
Manufacturer	OBO
Dimension	Ø12x30
Material	Die-cast zinc
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0196 kg CO2e / 1 Piece

Dimensions

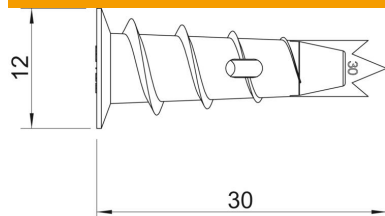

Length	30 mm
Dimension D	12 mm
Dimension L	30 mm

Technical data sheet

Plasterboard anchor

Item number: 3483214



Technical data

Version for	Plasterboard anchor
With thread	yes
With bolts	no
Permitted load range, tension zone	0.04