

Technical data sheet


MMS-plus F 7.5x80 countersunk head tie

Item number: 3498160



Bolt tie for direct mounting without additional anchors in cracked and uncracked concrete and masonry. With countersunk head for universal fastenings. Torx drive T40.

Construction product tested according to EAD and CE mark, with European Technical Assessment (ETA) and proof of suitability. Load-bearing capacities under fire loads proven up to fire resistance class R120.

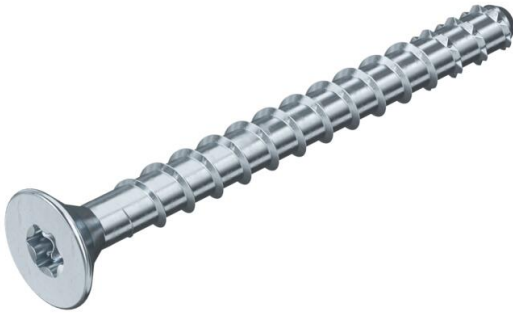

St Steel

VZ galvanised

Master data

Item number	3498160
Type	MMS+ F 7.5x80
Description 1	Countersunk anchor
Manufacturer	OBO
Dimension	7,5x80
Colour	zinc
Material	Steel
Surface	galvanised
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	2 kg
Weight unit	kg/100 pc.


Technical data sheet

MMS-plus F 7.5x80 countersunk head tie

Item number: 3498160



Dimensions

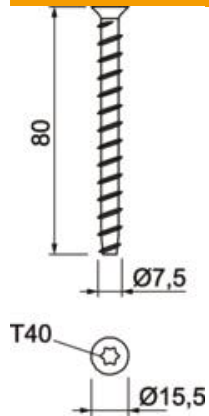

Dimension	7,5x80
Length	80 mm
Dimension L	80 mm

Technical data

Anchor/nail/bolt version	Spiral anchor
Drill hole diameter, min.	6 mm
Thread diameter ST	7.5
Head diameter	15.5 mm
Head shape	Countersunk head
Screw system	Torx