

Technical data sheet

MMS-plus P 7.5x75 round head tie, with pan head, made of A4 stainless steel

Item number: 3498274



Stainless steel screw-in anchor for direct mounting without additional anchors in cracked and uncracked concrete and masonry. With round head for universal fastenings in wet rooms and outdoor areas. Torx drive T30.

Construction product tested according to EAD and CE mark, with European Technical Assessment (ETA) and proof of suitability. Load-bearing capacities under fire loads proven up to fire resistance class R120.



A4 Stainless steel

Master data

Item number	3498274
Type	MMS+ P 7.5x75 A4
Description 1	Screw anchor
Description 2	with panhead
Manufacturer	OBO
Dimension	7,5x75mm
Colour	stainless steel
Material	Stainless steel 1.4401
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.9 kg
Weight unit	kg/100 pc.


Technical data sheet

MMS-plus P 7.5x75 round head tie, with pan head, made of A4 stainless steel

Item number: 3498274



Dimensions

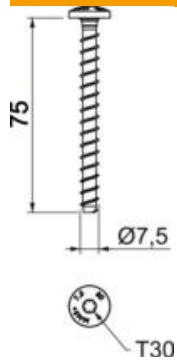

Dimension	7,5x75
Length	75 mm
Dimension L	75 mm

Technical data

Anchor/nail/bolt version	Spiral anchor
Drill hole depth	80 mm
Drill hole diameter, min.	6 mm
Hardened	yes
Thread diameter ST	7.5
Clamping strength	35 mm
Head diameter	14.5 mm
Head shape	Miscellaneous
Screw system	Torx
Fire resistance class EN 13501-1	R30 R60 R90 R120