

Technical data sheet

Hollow core anchor G

Item number: 3499042



Hollow core anchor with internal thread for anchoring, for example, cable tray constructions, pipes, suspended ceilings, wooden constructions, etc. on walls and ceilings made from stressed concrete hollow-core slabs in indoor and outdoor areas. With an edge to prevent the anchor from being pulled in. When the fastening screw is screwed in the expansion sleeve is spread open through the cone and tightens against the drill hole walls. Fire-safety tested, fire protection class R 120 according to European Technical Assessment ETA-21/0857.



St

Steel


G

Electrogalvanised

Master data

Item number	3499042
Type	FHY M8
Description 1	Hollow core anchor
Manufacturer	OBO
Dimension	12x43
Colour	zinc
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.3 kg
Weight unit	kg/100 pc.

Dimensions

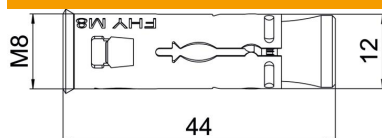

Technical data sheet

Hollow core anchor G

Item number: 3499042



Technical data

Drill hole depth	60 mm
Drill hole diameter, min.	12 mm
Thread	M8
Thread metric	8
Thread type	Metric
With thread	yes
With bolts	no