

Technical data sheet

Earth rod V4A 20 mm

Item number: 5000858



- "BP" system (Bundespost)
- Very good contacting properties with soft metal inlay in the bore hole
- With peg and bore for linking together
- Conforms to the requirements according to VDE 0185-305 (IEC 62305) and DIN EN 62561-2
- Short circuit current I_k (50 Hz), time 1 s, max. temp. 300 °C: 4.5 kA (219 20 BP V4A)



A4

Stainless steel

Master data

Item number	5000858
Type	219 20 BP V4A
Description 1	Earth rod
Manufacturer	OBO
Dimension	1m
Material	Stainless steel 1.4401
Smallest sales unit	5
Unit of quantity	Piece
Weight	250 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	12,3875 kg CO2e / 1 Piece


Technical data sheet

Earth rod V4A 20 mm

Item number: 5000858



Dimensions

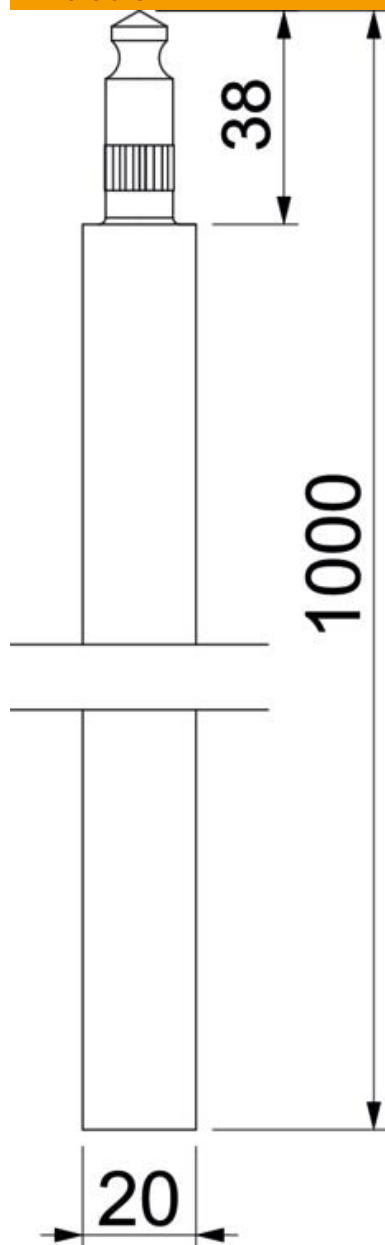

Length	1,000 mm
Dimension L	1,000 mm

Technical data sheet

Earth rod V4A 20 mm

Item number: 5000858



Technical data

Version for	Miscellaneous
Design earth rod	BP
Lightning current carrying capacity	H1/150 kA
Short-circuit current (50 HZ)(1 s; $\leq 300^{\circ}\text{C}$)	4.2 kA
Profile type	Round D=20 mm
Connection type	With pin/drill hole