


Technical data sheet

VARIO earthing terminal for reinforced steels

Item number: 5014468

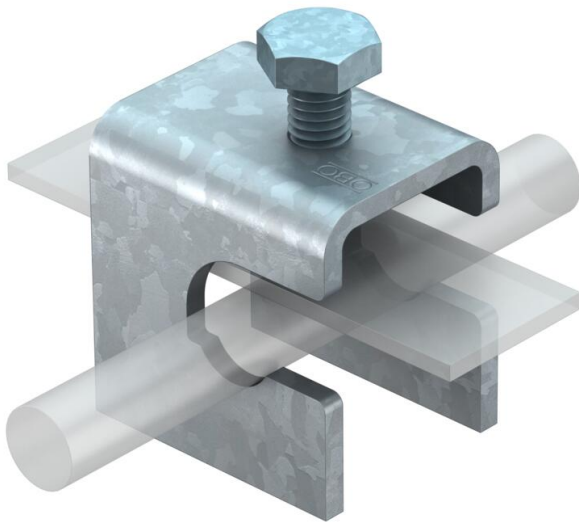

- For reinforced steels with diameters 8-14 mm and FL 30 x 5
- Simple mounting through open slot
- Side suspension possible



St

Steel

FT

Hot-dip galvanised

Master data

Item number	5014468
Type	1814 FT
Description 1	Variable earthing terminal
Description 2	for reinforcement
Manufacturer	OBO
Dimension	50x40x70
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	25
Unit of quantity	Piece
Weight	19.87 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,5934 kg CO2e / 1 Piece


Technical data sheet

VARIO earthing terminal for reinforced steels

Item number: 5014468



Dimensions

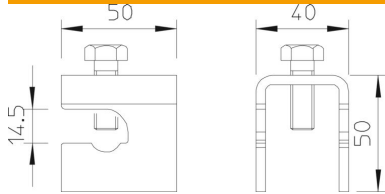

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Connectors
Lightning current carrying capacity	N/50 kA
Suitable for connection	Miscellaneous
Short-circuit current (50 HZ)(1 s; $\leq 300^{\circ}\text{C}$)	7.3 kA
Fit	FL30x5 x Rd8-14 mm