

Technical data sheet

Round conductor, galvanised steel

Item number: 5021050



- Can be used as a conductor according to DIN EN 62561-2 (VDE 0185-561-2)
- Corresponds to the requirements of VDE 0185-305 (IEC 62305)
- RD 10 can also be used in the earth
- Zinc coating: $\geq 350 \text{ g/m}^2$ (approx. $50 \text{ }\mu\text{m}$ as mean value)



St

Steel

FT

Hot-dip galvanised

Master data

Item number	5021050
Type	RD 8-FT 50
Description 1	Round conductors
Description 2	50 m ring
Manufacturer	OBO
Dimension	8mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	50
Unit of quantity	Metre
Weight	40 kg
Weight unit	kg/100 m


Technical data sheet

Round conductor, galvanised steel

Item number: 5021050



Dimensions

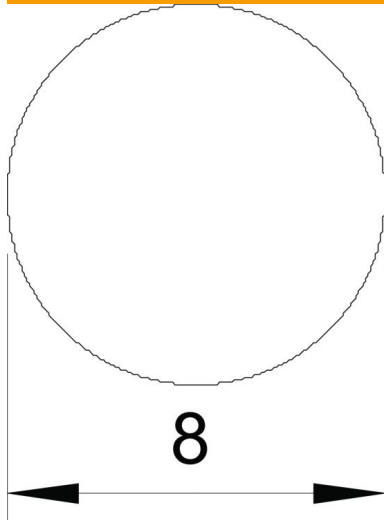

Dimension D	8 mm
-------------	------

Technical data

Number of individual wires	1
High voltage-resistant, insulated version	no
Nominal ring (approx. kg)	20
Nominal ring (approx. m)	50
Length tolerance $\pm$	5 %
Cross-section	50 mm ²
ROHS-conformant	yes
Material property	Miscellaneous
Material jacket	Without