

# Technical data sheet

## Spacer for flat conductor, with wood screw

Item number: 5030234



- Fit: FL 30 and FL 40
- With 2 cylinder bolts M5 x 12 (G) and over-piece
- With wood screw

|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanised |

### Master data

|                                    |                                |
|------------------------------------|--------------------------------|
| Item number                        | 5030234                        |
| Type                               | 708 30 HG                      |
| Description 1                      | Spacer                         |
| Description 2                      | w. thread for ground conductor |
| Manufacturer                       | OBO                            |
| Dimension                          | 30mm                           |
| Material                           | Steel                          |
| Surface                            | Electrogalvanised              |
| Surface standard                   | EN ISO 19598 / EN ISO 4042     |
| Smallest sales unit                | 50                             |
| Unit of quantity                   | Piece                          |
| Weight                             | 2.536 kg                       |
| Weight unit                        | kg/100 pc.                     |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0609 kg CO2e / 1 Piece       |


# Technical data sheet

## Spacer for flat conductor, with wood screw

Item number: 5030234



### Dimensions

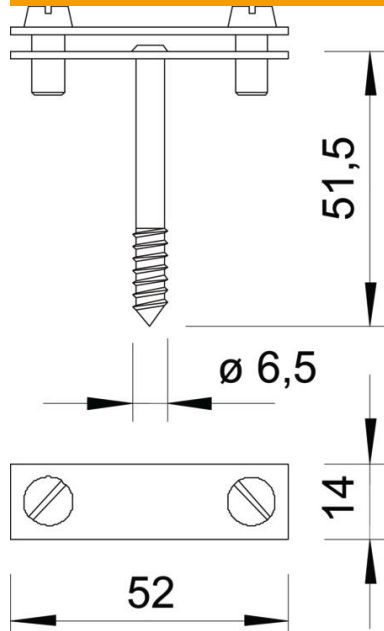

|             |       |
|-------------|-------|
| Dimension B | 52 mm |
|-------------|-------|

### Technical data

|                    |              |
|--------------------|--------------|
| Fit                | max. FL30 mm |
| ROHS-conformant    | yes          |
| Intermediate plate | no           |