

Technical data sheet

Earthing clamp, type 942

Item number: 5038030



- For pipes 1/8–1 1/2" or Ø 8–49 mm
- Connection options: Cables up to 25 mm²
- With connection clip and cylinder bolt M6 x 16 made of brass, nickel-plated
- Clamp cover and base made of copper, nickel-plated

Cu	Copper
N	Nickel-plated

Master data

Item number	5038030
Type	942 15
Description 1	Earthing clamp
Manufacturer	OBO
Dimension	13-15mm
Material	Copper
Surface	Nickel-plated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	4.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1621 kg CO2e / 1 Piece



Technical data sheet

Earthing clamp, type 942

Item number: 5038030



Dimensions

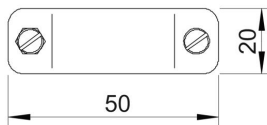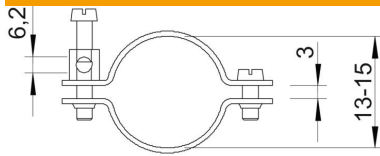

Dimension A	50 mm
Dimension b	20 mm
Dimension X	3 mm

Technical data

Number of conductors	1
Cross-section of cable to be connected, max.	25 mm ²
Cross-section of cable to be connected, min.	0 mm ²
ROHS-conformant	Exempt
Clamping range D	1/4
Clamping range D, max.	15 mm
Clamping range D, min.	13 mm