


Technical data sheet

Roof conductor holder for ridge tiles, metal roofs, Rd 8

Item number: 5202510

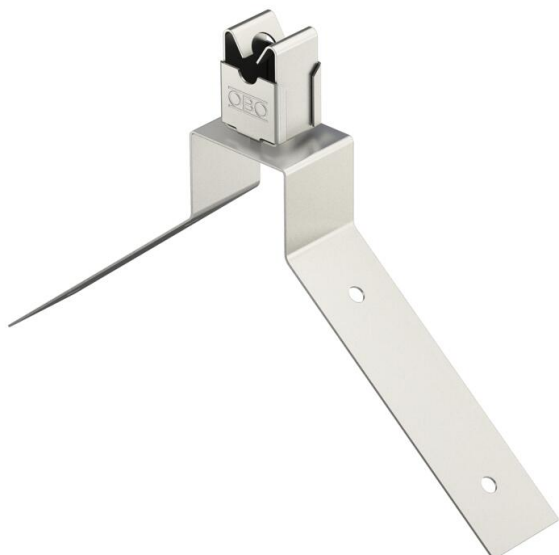

- For round conductors Rd 8
- Suitable for metal roofs

A2 Stainless steel

Master data

Item number	5202510
Type	132 P VA
Description 1	Roof conductor holder
Description 2	for metal roofs
Manufacturer	OBO
Dimension	8mm
Colour	stainless steel
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	8.42 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,5343 kg CO2e / 1 Piece


Technical data sheet

Roof conductor holder for ridge tiles, metal roofs, Rd 8

Item number: 5202510



Dimensions

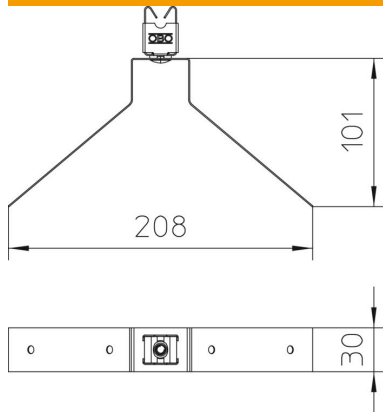

Length	30 mm
Width	208 mm

Technical data

Application	Ridge
Conductor fastening type	With clip
Conductor diameter, max.	8
Conductor diameter, min.	8
Mounting type	Tensionable
Mounting height	20 mm
Fit	Rd 8 mm
ROHS-conformant	yes
Clamping range D, max.	8 mm
Clamping range D, min.	8 mm
Material of the holder	Rustproof steel (V2A)
Material of the support	Rustproof steel (V2A)