

Technical data sheet

Roof conductor holder for ridge tiles, 180–240 mm, Rd
8–10, FT
Item number: 5202566



- Adjustable from 180–240 mm
- With conductor 177/20, polyamide, grey
- With 3 M8 threaded nipples for positioning the holder

St	Steel
FT	Hot-dip galvanised

Master data


Item number	5202566
Type	132 N-DK
Description 1	Roof conductor holder
Description 2	for ridge tiles
Manufacturer	OBO
Dimension	8mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	20
Unit of quantity	Piece
Weight	19.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4988 kg CO2e / 1 Piece

Technical data sheet

Roof conductor holder for ridge tiles, 180–240 mm, Rd
8–10, FT
Item number: 5202566



Dimensions

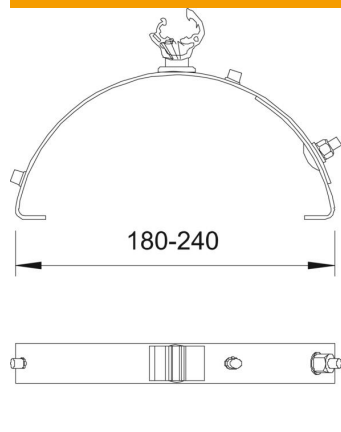

Length	25 mm
Height	122 mm

Technical data

Application	Ridge
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Tensionable
Mounting height	20 mm
Fit	Rd 8-10 mm
ROHS-conformant	yes
Clamping range D, max.	240 mm
Clamping range D, min.	180 mm
Material of the holder	Plastic
Material of the support	Steel, hot galvanised