

Technical data sheet

Roof cable holder for ridge tiles with M8 threaded bolts

Item number: 5202568



- Adjustable from 180–240 mm
- With conductor 177/20, polyamide, grey
- With 3 M8 threaded nipples for positioning the holder

St

Steel

FT

Hot-dip galvanised

Master data

Item number	5202568
Type	132 GB-M8
Description 1	Roof conductor holder
Description 2	for ridge tiles with M8 bolt
Manufacturer	OBO
Dimension	M8
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	20
Unit of quantity	Piece
Weight	18.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4358 kg CO2e / 1 Piece


Technical data sheet

Roof cable holder for ridge tiles with M8 threaded bolts

Item number: 5202568



Dimensions

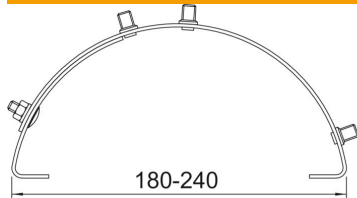

Length	25 mm
Height	113.5 mm



Technical data

Application	Ridge
Mounting type	Tensionable
ROHS-conformant	yes
Clamping range D, max.	240 mm
Clamping range D, min.	180 mm
Material of the support	Steel, hot galvanised