

Technical data sheet

Roof conductor holder for slated roofs

Item number: 5202569




- With Ø 5.5 mm drill hole
- With 3 M8 threaded nipples for positioning the holder

A2 Stainless steel

Master data

Item number	5202569
Type	157 GB-M8
Description 1	Roof conductor holder
Description 2	for slate roofs with M8 GB
Manufacturer	OBO
Dimension	260mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2694 kg CO2e / 1 Piece

Dimensions

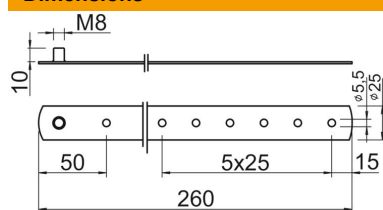

Length	260 mm
--------	--------

Technical data

Application	Slate roof
Conductor fastening type	Miscellaneous
Mounting type	Screw-on
Mounting height	27 mm
Fit	Rd 8-10 mm
ROHS-conformant	yes
Material of the support	Rustproof steel (V2A)