

Technical data sheet

Ridge conductor holder with tensioning spring

Item number: 5203018



- For round conductor Rd 8
- Clamping range 280-380 mm



A2 Stainless steel

Master data

Item number	5203018
Type	132 U 35
Description 1	Ridge conductor holder
Description 2	variable length adjustment
Manufacturer	OBO
Dimension	8 mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	6.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4108 kg CO2e / 1 Piece


Technical data sheet

Ridge conductor holder with tensioning spring


Item number: 5203018



Dimensions

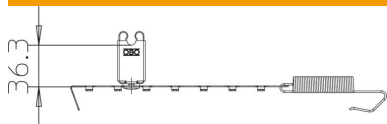

Length	275 mm
Width	28 mm
Height	36.3 mm

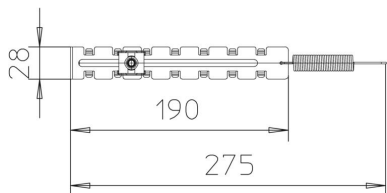

Technical data

Application	Ridge
Conductor fastening type	With clip
Conductor diameter, min.	8
Mounting type	Tensionable
Mounting height	35 mm
Fit	RD 8 mm
ROHS-conformant	yes
Clamping range D, max.	380 mm
Clamping range D, min.	280 mm
Material of the holder	Rustproof steel (V2A)
Material of the support	Rustproof steel (V2A)