


Technical data sheet

Ridge conductor holder with tensioning spring

Item number: 5203023



- For round conductor Rd 8
- Clamping range 280-380 mm

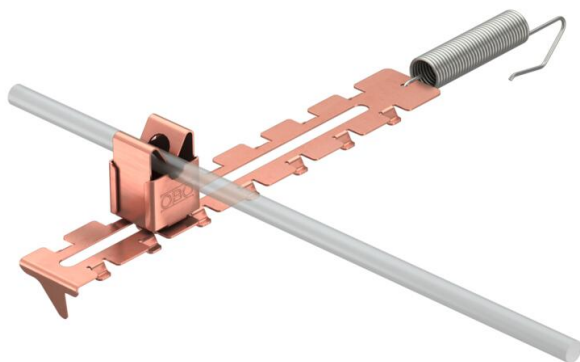

A2	Stainless steel
Cu	Copper-plated

Master data

Item number	5203023
Type	132 U-CU
Description 1	Ridge conductor holder
Description 2	variable length adjustment
Manufacturer	OBO
Dimension	8mm
Material	Stainless steel 1.4301
Surface	Copper-plated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1062 kg CO2e / 1 Piece

Technical data sheet

Ridge conductor holder with tensioning spring

Item number: 5203023



Dimensions



Length	275 mm
Width	28 mm
Height	28.3 mm



Technical data

Application	Ridge
Conductor fastening type	With clip
Conductor diameter, min.	8
Mounting type	Tensionable
Mounting height	20 mm
Fit	RD 8 mm
Clamping range D, max.	380 mm
Clamping range D, min.	280 mm
Material of the holder	Copper
Material of the support	Rustproof steel (V2A)