

Technical data sheet

Cable bracket, raised construction type, for Rd 8 mm,
through-way Ø 5 mm
Item number: 5207342



- With female thread M6 or through hole Ø 5 mm
- From stainless steel (V2A)

A2 Stainless steel


Master data		
Item number	5207342	
Type	177 35 VA M6	
Description 1	Cable fixing device	
Manufacturer	OBO	
Dimension	8mm	
Material	Stainless steel 1.4301	
Smallest sales unit	20	
Unit of quantity	Piece	
Weight	2.68 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1331 kg CO2e / 1 Piece	

Technical data sheet

Cable bracket, raised construction type, for Rd 8 mm,
through-way Ø 5 mm
Item number: 5207342



Dimensions

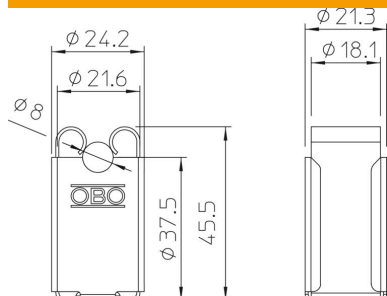

Length	24.2 mm
Dimension G	M6 mm

Technical data

Holder fastening type	Drill hole with M-thread
Conductor fastening type	With clip
Thread metric	6
Cable dimensions	8 mm round
Mounting height	35 mm
Fit	Rd 8 mm
ROHS-conformant	yes