

Technical data sheet

Cable bracket for Rd 8 mm, through-way Ø 7 mm

Item number: 5207347



- With female thread M8 or through hole Ø 7 mm
- From stainless steel (V2A)

A2 Stainless steel

Master data

Item number	5207347
Type	177 20 VA M8
Description 1	Cable fixing device
Description 2	for round conductors
Manufacturer	OBO
Dimension	8mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	1.838 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,093 kg CO2e / 1 Piece


Technical data sheet

Cable bracket for Rd 8 mm, through-way Ø 7 mm

Item number: 5207347



Dimensions

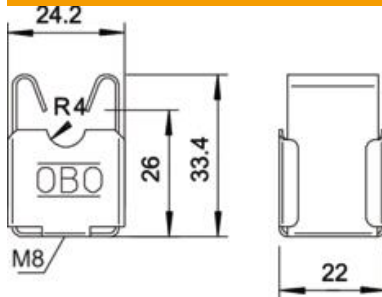

Length	24.2 mm
--------	---------

Technical data

Holder fastening type	Drill hole with M-thread
Conductor fastening type	With clip
Thread metric	8
Cable dimensions	8 mm round
Mounting height	20 mm
Fit	Rd 8 mm
ROHS-conformant	yes