


Technical data sheet

Cable bracket Rd 8–10 mm, copper-plated

Item number: 5207754



- With female thread M8 for screwing and through hole for wood screws
- Colour: copper
- Weather and temperature-resistant from -35 °C to +90 °C

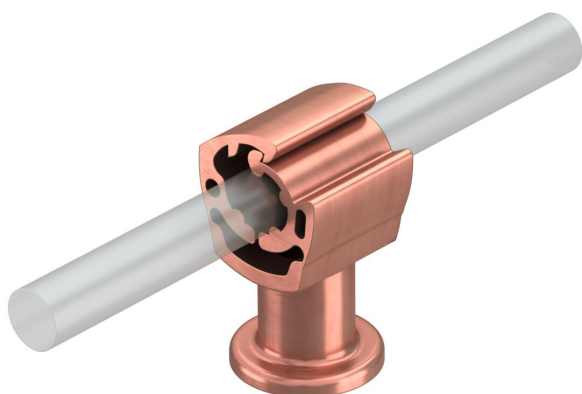

PA Polyamide

Master data

Item number	5207754
Type	177 30 CU
Description 1	Cable fixing device
Manufacturer	OBO
Dimension	30mm
Colour	Copper
Material	Polyamide
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.784 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0367 kg CO2e / 1 Piece


Technical data sheet

Cable bracket Rd 8–10 mm, copper-plated

Item number: 5207754



Dimensions

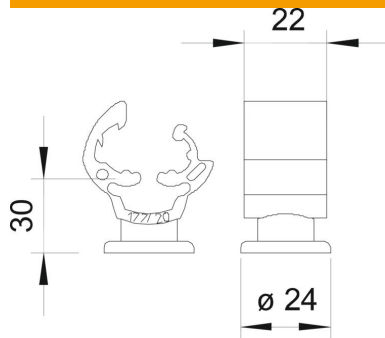

Technical data

Holder fastening type	Drill hole with M-thread
Conductor fastening type	With clamp clip
Thread metric	8
Cable dimensions	8–10 mm round
Mounting height	30 mm
Fit	Rd 8-10 mm
Material of the holder	Polyamide
Material of the base	Polyamide
Material of the crossbar	Polyamide