

Technical data sheet

Cable bracket for Rd 8 mm, through-way Ø 7 mm, copper-plated

Item number: 5207819



- With female thread M8 or through hole Ø 5 mm
- From stainless steel (V2A)
- VA-VK: copper-plated

A2	Stainless steel
Cu	Copper-plated

Master data

Item number	5207819
Type	177 20 VA-VK M8
Description 1	Cable fixing device
Manufacturer	OBO
Dimension	8mm
Material	Stainless steel 1.4301
Surface	Copper-plated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	1.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0078 kg CO2e / 1 Piece


Technical data sheet

Cable bracket for Rd 8 mm, through-way Ø 7 mm, copper-plated

Item number: 5207819



Dimensions

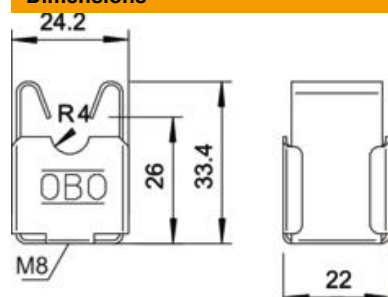

Length	24.2 mm
--------	---------

Technical data

Conductor fastening type	With clip
Cable dimensions	8 mm round
Mounting height	20 mm
Fit	Rd 8 mm
ROHS-conformant	yes