


Technical data sheet

Roof conductor holder for tiled and slated roofs

Item number: 5215307



- High roof conductor holder: 74 mm
- With perforation Ø 5.5 mm
- Polyamide cable bracket

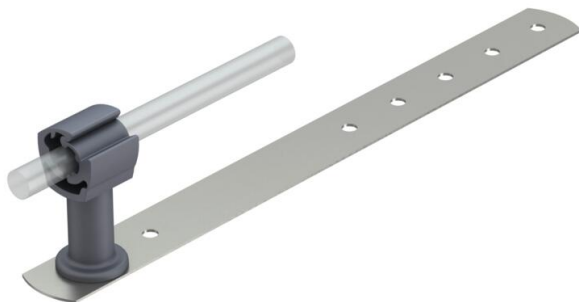

A2 Stainless steel

Master data

Item number	5215307
Type	157 ND-VA
Description 1	Roof conductor holder
Description 2	for slated roofs
Manufacturer	OBO
Dimension	260mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3153 kg CO2e / 1 Piece

Technical data sheet

Roof conductor holder for tiled and slated roofs

Item number: 5215307



Dimensions



Length	260 mm
Width	25 mm
Height	74 mm

Technical data

Application	Roof surface
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	74 mm
Fit	Rd 8-10 mm
ROHS-conformant	yes
Material of the holder	Plastic
Material of the support	Rustproof steel (V2A)