


Technical data sheet

Roof conductor holder for slated roofs, Rd 8–10, A2

Item number: 5215374



- With Ø 5.5 mm drill hole and beading
- Conductor holder of polyamide

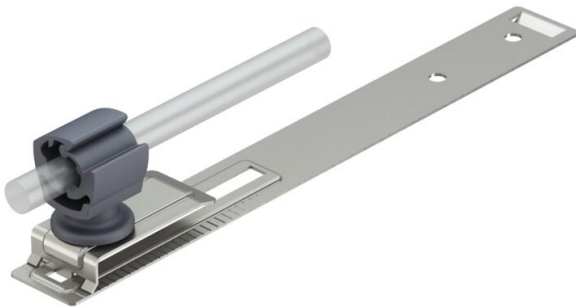

A2 Stainless steel

Master data

Item number	5215374
Type	157 LK-VA
Description 1	Roof conductor holder
Description 2	adjustable length
Manufacturer	OBO
Dimension	8-10 mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3505 kg CO2e / 1 Piece


Technical data sheet

Roof conductor holder for slated roofs, Rd 8–10, A2

Item number: 5215374



Dimensions

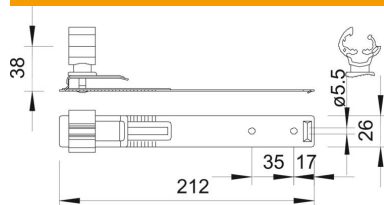

Length	212 mm
Width	26 mm
Height	38 mm

Technical data

Application	Roof surface
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	38 mm
Fit	Rd 8-10 mm
ROHS-conformant	yes
Material of the holder	Plastic
Material of the support	Rustproof steel (V2A)