


Technical data sheet

Roof cable holder for slated roofs, Rd 8–10, CU

Item number: 5215382



- With Ø 5.5 mm drill hole and beading
- Conductor holder of polyamide

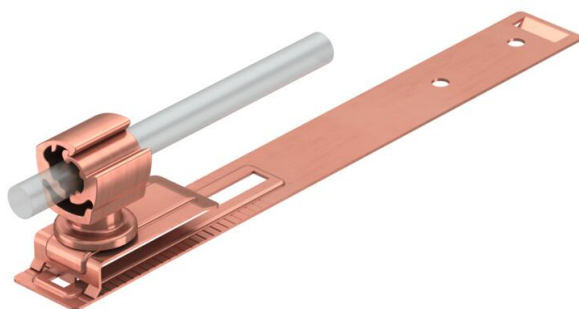

Cu Copper

Master data

Item number	5215382
Type	157 LK-CU
Description 1	Roof conductor holder
Description 2	adjustable length
Manufacturer	OBO
Dimension	210mm
Material	Copper
Smallest sales unit	10
Unit of quantity	Piece
Weight	8.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2634 kg CO2e / 1 Piece


Technical data sheet

Roof cable holder for slated roofs, Rd 8–10, CU

Item number: 5215382



Dimensions

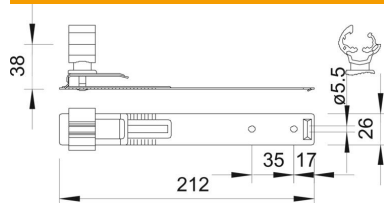

Length	212 mm
--------	--------

Technical data

Application	Roof surface
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	38 mm
Fit	Rd 8-10 mm
Material of the holder	Plastic
Material of the support	Copper