

Technical data sheet

Roof conductor holder for tiled roofs, Rd 8–10

Item number: 5215544



- Conductor holder of polyamide
- Including drill hole in bottom section for quick installation




A2 Stainless steel

Master data

Item number	5215544
Type	157 FK-VA 230
Description 1	Roof conductor holder
Manufacturer	OBO
Dimension	8mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	7.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3 kg CO2e / 1 Piece

Dimensions

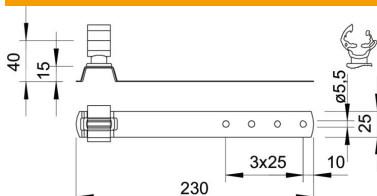

Length	230 mm
Width	25 mm
Height	40 mm
Dimension L	230 mm

Technical data sheet

Roof conductor holder for tiled roofs, Rd 8–10

Item number: 5215544



Technical data

Application	Roof surface
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	40 mm
Fit	Rd 8-10 mm
ROHS-conformant	yes
Material of the holder	Plastic
Material of the support	Rustproof steel (V2A)