

Technical data sheet

Roof conductor holder for tiled roofs, Rd 8

Item number: 5215552



- Conductor holder from stainless steel (V2A)
- Including drill hole in bottom section for quick installation



A2 Stainless steel

Master data		
Item number	5215552	
Type	157 F-VA 230	
Description 1	Roof conductor holder	
Manufacturer	OBO	
Dimension	8mm	
Material	Stainless steel 1.4301	
Smallest sales unit	20	
Unit of quantity	Piece	
Weight	8.35 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,3742 kg CO2e / 1 Piece	


Technical data sheet

Roof conductor holder for tiled roofs, Rd 8

Item number: 5215552



Dimensions

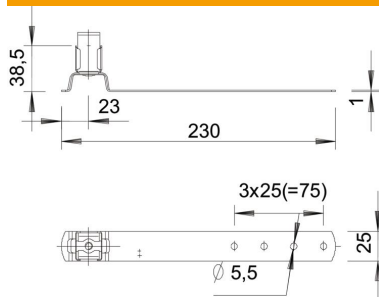

Length	230 mm
Width	25 mm
Height	38.5 mm
Dimension L	230 mm

Technical data

Application	Roof surface
Conductor fastening type	With clip
Conductor diameter, max.	8
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	38.5 mm
Fit	Rd 8 mm
ROHS-conformant	yes
Material of the holder	Rustproof steel (V2A)
Material of the support	Rustproof steel (V2A)