

Technical data sheet

Roof conductor holder for tiled roofs, angled, Rd 8

Item number: 5215625



- Conductor holder high-grade stainless steel (V2A)
- Curved bottom strip for quick installation



A2 Stainless steel

Master data

Item number	5215625
Type	157 I-VA
Description 1	Roof conductor holder
Manufacturer	OBO
Dimension	8mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	7.15 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3319 kg CO2e / 1 Piece


Technical data sheet

Roof conductor holder for tiled roofs, angled, Rd 8

Item number: 5215625



Dimensions

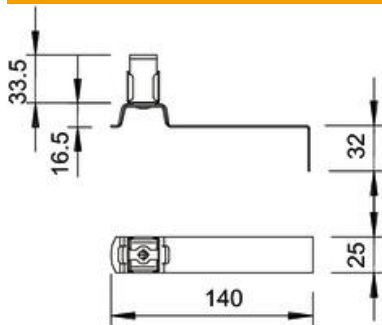

Length	140 mm
Width	25 mm
Height	38.5 mm

Technical data

Application	Roof surface
Conductor fastening type	With clip
Conductor diameter, min.	8
Mounting type	For suspension
Mounting height	26.5 mm
Fit	Rd 8 mm
ROHS-conformant	yes
Material of the holder	Rustproof steel (V2A)
Material of the support	Rustproof steel (V2A)