

Technical data sheet

Roof conductor holder for slated roofs, crimped, Rd 8–10, A2

Item number: 5215838



- Conductor holder of polyamide
- With Ø 5.5 mm drill hole




A2 Stainless steel

Master data

Item number	5215838
Type	157 EK-VA
Description 1	Roof conductor holder
Manufacturer	OBO
Dimension	8mm
Material	Stainless steel 1.4301
Smallest sales unit	20
Unit of quantity	Piece
Weight	7.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,351 kg CO2e / 1 Piece

Dimensions

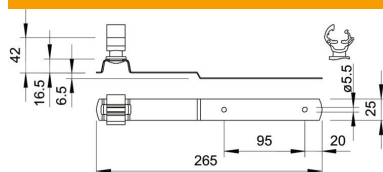

Length	265 mm
Width	25 mm
Height	42 mm

Technical data sheet

Roof conductor holder for slated roofs, crimped, Rd 8–10, A2

Item number: 5215838



Technical data

Application	Roof surface
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	42 mm
Fit	Rd 8-10 mm
Material of the holder	Plastic
Material of the support	Rustproof steel (V2A)