

Technical data sheet

Roof conductor holder for tiled roofs, angled, Rd 8

Item number: 5215875



- With flexible bottom section from aluminium for matching to roof tiles (easy to flex)
- Holder from stainless steel (V2A)
- Curved bottom section for quick installation

Alu Aluminium

Master data

Item number	5215875
Type	157 FX-AL
Description 1	Roof conductor holder
Description 2	with flexible base
Manufacturer	OBO
Dimension	8mm
Material	Aluminium
Smallest sales unit	20
Unit of quantity	Piece
Weight	3.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3233 kg CO2e / 1 Piece


Technical data sheet

Roof conductor holder for tiled roofs, angled, Rd 8

Item number: 5215875



Dimensions

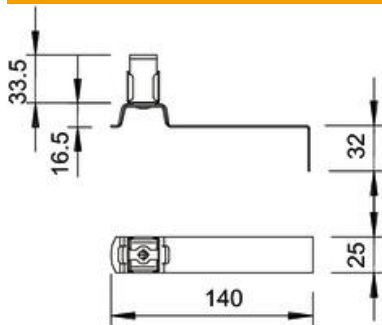

Length	140 mm
Width	25 mm
Height	38.5 mm

Technical data

Application	Roof surface
Conductor fastening type	With clip
Conductor diameter, max.	8
Conductor diameter, min.	8
Mounting type	For suspension
Mounting height	26.5 mm
Fit	Rd 8 mm
ROHS-conformant	yes
Material of the holder	Rustproof steel (V2A)
Material of the support	Aluminium