

Technical data sheet

Roof conductor holder 55 mm

Item number: 5218314



- Suitable for bonding straight to flat roofs
- Conductor holder of polyamide
- Bottom section, hot-dip galvanised steel
- Bottom section Ø 100 mm

PA Polyamide

Master data

Item number	5218314
Type	165 NBK 55
Description 1	Roof conductor holder
Manufacturer	OBO
Dimension	55mm
Material	Polyamide
Smallest sales unit	75
Unit of quantity	Piece
Weight	13.54 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3801 kg CO2e / 1 Piece

Technical data sheet

Roof conductor holder 55 mm


Item number: 5218314



Dimensions



Length	100 mm
Dimension H	55 mm

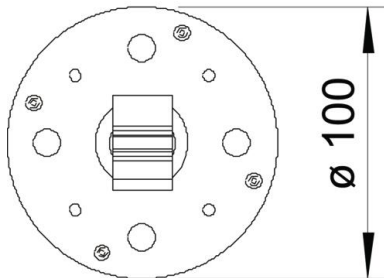

Technical data

Application	Flat roof
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Adhesive
Mounting height	55 mm
Fit	Rd 8-10 mm
ROHS-conformant	yes
Material of the holder	Plastic
Material of the support	Steel, hot galvanised