

Technical data sheet

165 MBG... roof cable holder for flat roofs, grey, with concrete

Item number: 5218708



- Closed form with base
- With double conductor holder
- Filling weight 1 kg (frost resistant concrete)
- Case made from polyethylene, light grey, UV-resistant and weatherproof
- Base made from polyamide PA 6, light grey, UV-resistant and weatherproof
- Base suitable for nearly all roofing membrane systems (bitumen, PVC)

PA/
PE

Polyamide/Polyethylene

Master data	
Item number	5218708
Type	165 MBG-8-10 GR
Description 1	Roof conductor holder
Description 2	for flat roofs
Manufacturer	OBO
Dimension	8-10mm
Colour	Grey
Material	Polyamide/Polyethylene
Smallest sales unit	12
Unit of quantity	Piece
Weight	100 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4732 kg CO2e / 1 Piece


Technical data sheet

165 MBG... roof cable holder for flat roofs, grey, with concrete


Item number: 5218708



Dimensions

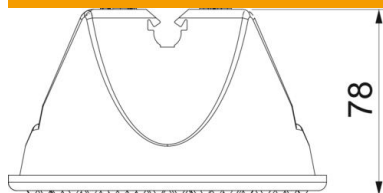

Length	133.5 mm
--------	----------

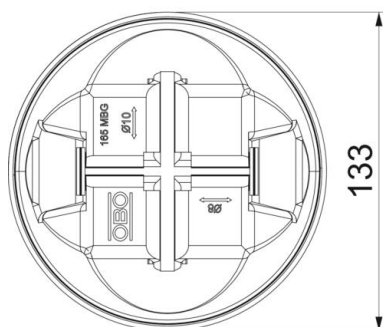

Technical data

Application	Flat roof
Conductor fastening type	With clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Miscellaneous
Fit	Rd 8-10 mm
ROHS-conformant	yes
Material of the holder	Plastic
Material of the support	Concrete