

Technical data sheet

165 MBG... roof cable holder for flat roofs, with increased base section

Item number: 5218716



- Closed form with base
- With double conductor holder
- Filling weight 1 kg (frost-resistant concrete)
- Sleeve from polyethylene, black, UV-resistant and weatherproof
- Base made of polypropylene, black, UV-resistant and weather-resistant
- With larger base section (Ø 200 mm) for better stability

PP/PE Polypropylene/polyethylene

Master data

Item number	5218716
Type	165 MBG-8-10 200
Description 1	Roof conductor holder
Description 2	for flat roofs
Manufacturer	OBO
Dimension	8-10mm
Colour	Black
Material	Polypropylene/polyethylene
Smallest sales unit	4
Unit of quantity	Piece
Weight	104.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,6741 kg CO2e / 1 Piece


Technical data sheet

165 MBG... roof cable holder for flat roofs, with increased base section

Item number: 5218716



Dimensions

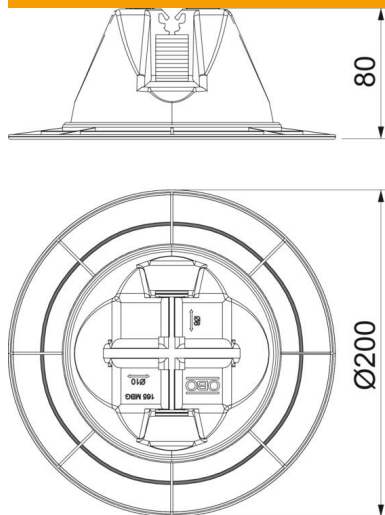

Height	80 mm
--------	-------

Technical data

Application	Flat roof
Conductor fastening type	With clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Miscellaneous
Fit	Rd 8-10 mm
ROHS-conformant	yes
Material of the holder	Plastic
Material of the support	Concrete